

# COMPACT



stay connected

## Xenterra



Xenterra is Murrelektronik's new unmanaged switch family. With a flat design, this robust switch is ideal for panels where space is at a premium as it can be ordered as a DIN rail mountable version or with wall mounting brackets. Since it is available in your choice of a 5, 8 or 16 port version you can be sure you are getting just what you need for your installation.

### MURRELEKTRONIK Related Products

IP67 Switches



Tree




RJ45 Pro






RJ45 Heavy Duty

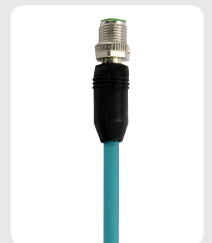

Ethernet Cable



	Xenterra 5TX		Xenterra 8TX		Xenterra 16TX	
						
<b>Article Number</b>	<b>58900</b>	<b>58901</b>	<b>58902</b>	<b>58903</b>	<b>58904</b>	<b>58905</b>
Ports	5 x RJ45		8 x RJ45		16 x RJ45	
Temperature Range	-40 - 70°C (storage temperature -40 - 85°C)					
Dimensions (H x W x D)	105 x 32.5 x 42mm	105 x 69 x 28mm	105 x 32.5 x 58mm	105 x 85 x 28mm	105 x 32.5 x 110mm	105 x 137 x 28mm
Status Display	LED					
Operating Voltage	9 - 36V DC					
Connection	Spring Clamp Terminals (.25-1.5mm <sup>2</sup> )					
Transfer Rate	10/100Mbit/s full or half duplex					
Mounting	DIN Rail	Wall Mount	DIN Rail	Wall Mount	DIN Rail	Wall Mount
Housing	Anodized aluminum, stainless steel					
Approvals	cULus					

## ETHERNET/ProFiNET/EtherCAT

### MALE STRAIGHT to MALE STRAIGHT



Poles	Jacket Color	Cable Type	Length (m)	Art. Number
4	Teal	TPE	1.5, 3, 5, 7.5, 10	7700-44511-S4Uyyyy

### RJ45 - RJ45



Poles	Jacket Color	Cable Type	Length (m)	Art. Number
4	Teal	TPE	1.5, 3, 5, 7.5, 10	7700-74301-S4Uyyyy

### MALE M12 - RJ45



Poles	Jacket Color	Cable Type	Length (m)	Art. Number
4	Teal	TPE	1.5, 3, 5, 7.5, 10	7700-44711-S4Uyyyy

Standard Lengths in Meters (yyyy)				
1.5 (0150)	3 (0300)	5 (0500)	7.5 (0750)	10 (1000)

### RJ45 CABINET CABLES (Cat 6<sub>A</sub> - 10Gbit/s)



Cable	Jacket Color	Cable Type	Length	Art. Number
.14m <sup>2</sup> wire cross section (AWG26)	Gray	FRNC/LSOH	.3m	7000-74711-7780030
			.6m	7000-74711-7780060
			1m	7000-74711-7780100
			3m	7000-74711-7780300
			5m	7000-74711-7780500
			7.5m	7000-74711-7780750
			10m	7000-74711-7781000

### RJ45 & USB PANEL PASS-THROUGH



Style	Art. Number
4-pole M12 D-coded/RJ45 Adapter, Straight	7000-44671-0000000
4-pole M12 D-coded/RJ45 Adapter, 90°	7000-44681-0000000
M12/M12 4-pole, D coded	7000-44611-0000000