

➤ M8/M12 Adapters

Make the right connection

The most innovative products emerge from the implementation of our customers' suggestions and needs. Like our range of M8/M12 adapters. Whether it's the dark-bright switching of light barriers, the adaptation of M8 sensors to M12 connection cables or special pressure-switch circuits their uses are as numerous as the variations in the range.

Technical Data for M8/M12 adapters:

Connection Voltage: 24V AC/DC

Supply current: max. 4A

Protection: IP67

Temperature Range: -25°C - 85°C



M8 - M8



M8 - M12



M12 - M12



M12 - M8

- Allow for more flexibility
- Tailored to a wide range of customer applications
- Variety of circuit options:
 - M8 - M8
 - M8 - M12
 - M12 - M12
 - M12 - M8

MURRELEKTRONIK Related Products


Valve Plugs



Cordsets



Exact12

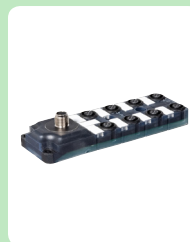

Cube67



Impact67



Standard Adapters

Adapter	Male	Female	Circuit Diagram	Art. Number
M12 Male - M12 Female	4-pole	4-pole		7000-41241-0000000
M12 Male - M12 Female	5-pole	5-pole		7000-42281-0000000
M12 Male - M8 Female	3-pole	3-pole		7000-42201-0000000
M12 Male - M8 Female	4-pole	4-pole		7000-42211-0000000
M8 Male - M12 Female	3-pole	3-pole		7000-88521-0000000
M8 Male - M12 Female	4-pole	4-pole		7000-88531-0000000
M8 Male - M8 Female	4-pole	3-pole		7000-88501-0000000
M8 Male - M8 Female	3-pole	4-pole		7000-88511-0000000

T-Couplers

T-Couplers							
Type	M12-M12	M12-M12 with Fixed Coupling Nut			M12-M8		
Art. Number	7000-41121-0000000	7000-41181-0000000	7000-41131-0000000	7000-41191-0000000	7000-41135-0000000	7000-41211-0000000	7000-41231-0000000
# of Poles	5				5 with LED	4	3
Circuit Diagram							

Murrelektronik has more custom models available. If you do not see what you are looking for, contact your Murrelektronik sales manager to discuss your application.

